

Part No: 3976-908

Fabricated DWV

Double Wye

Desc: 24X8 PVC RED DBL WYE SOC N.P.R. SCH80

MSRP: 5296.76

Part Code: 400

Weight(lbs): 282.805

Weight(kg): 128.278

Weight(gm): 128278

Size: 24 X 8


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

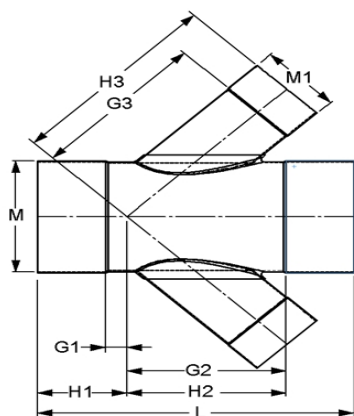

L = 51-1/2

M = 26-7/16

M1 = 9-5/8

G1 = 1-3/4

G2 = 25-3/4

G3 = 25-3/4

H1 = 13-3/4

H2 = 37-3/4

H3 = 30

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

