

Part No: 3976-910

Fabricated DWV

Double Wye

Desc: 24X10 PVC RED DBL WYE SOC NPR SCH80

MSRP: 5567.08

Part Code: 400

Weight(lbs): 319.814

Weight(kg): 145.065

Weight(gm): 145065

Size: 24 X 10


Color: GRAY

Material: PVC

Schedule SCH 80 DWV

Type Reducing

Connection Socket x Socket x Socket x Socket

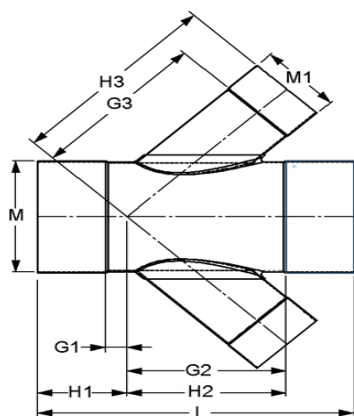

G1 = 3-1/4

G2 = 27-1/4

G3 = 27-3/8

H1 = 15-1/4

H2 = 39-1/4

H3 = 32-5/8

L = 54-1/2

M = 26-7/16

M1 = 11-15/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.


L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

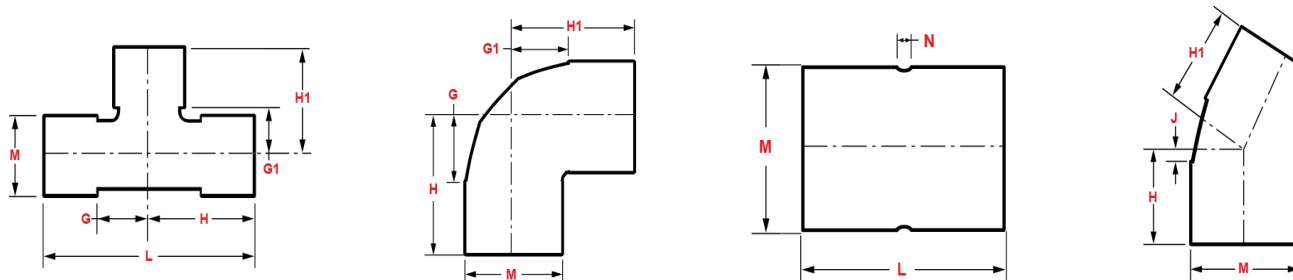

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006