

Part No: 3976-914C

Fabricated CPVC Schedule 80 Double Wye DWV

Desc: 24X14 CPVC RED DBL WYE SOC SCH80 N.P.R.

MSRP: 31590.96

Part Code: 099

Weight(lbs): 381.969

Weight(kg): 173.258


Weight(gm): 173258

Size: 24 X 14

Color: GRAY

Material: CPVC

Connection Socket x Socket x Socket x Socket
Type Reducing

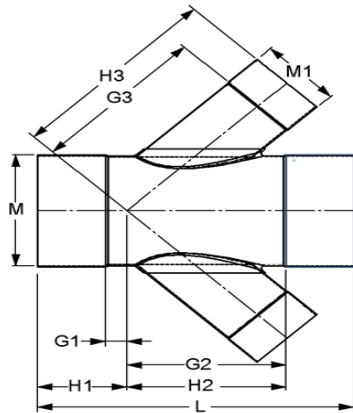

G1 = 6-1/4

G2 = 30-1/4

G3 = 30-1/4

H1 = 18-1/4

H2 = 42-1/4

H3 = 37-1/4

L = 60-1/2

M = 26-7/16

M1 = 15-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

