

Part No: 3977-080C

Fabricated CPVC Schedule 80 Combo Wye & 1/8 Bend DWV

Desc: 8 CPVC COMB WYE&1/8 BEND SOC SCH80 NPR

MSRP: 2154.16

Part Code: 099

Weight(lbs): 40.565

Weight(kg): 18.4

Weight(gm): 18400


Size: 8

Color: GRAY

Material: CPVC

Type Standard

Connection Socket x Socket x Socket

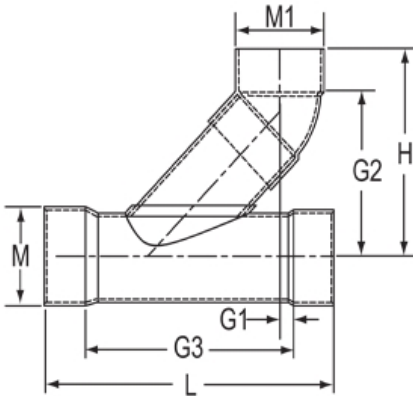

M = 9-5/8

M1 = 9-3/4

G1 = 7/16

G2 = 19-3/16

G3 = 16-1/8

H = 20-1/8

L = 27-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

