

Part No: 3977-100

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 10 PVC COMB WYE&1/8 BEND SOC SCH80 N.P.R

MSRP: 1586.7

Part Code: 400

Weight(lbs): 71.52

Weight(kg): 32.441

Weight(gm): 32441


Size: 10

Color: GRAY

Material: PVC

Schedule SCH 80 DWV - Standard

Connection Socket x Socket x Socket

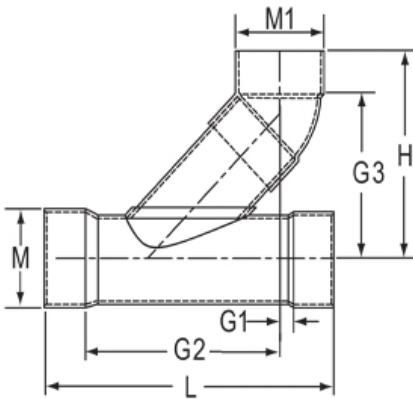

G1 = 1/4

G2 = 23-1/2

G3 = 19-9/16

H = 24-11/16

L = 34-1/4

M = 11-15/16

M1 = 12-1/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

