

Part No: 3977-528C

Fabricated CPVC Schedule 80 Combo Wye & 1/8 Bend DWV

Desc: 6X2 CPVC RED COMB WYE&1/8 BEND SOC SCH80

MSRP: 1027.84

Part Code: 099

Weight(lbs): 10.375

Weight(kg): 4.706

Weight(gm): 4706


Size: 6 X 2

Color: GRAY

Material: CPVC

Type Reducer

Connection Socket x Socket x Socket

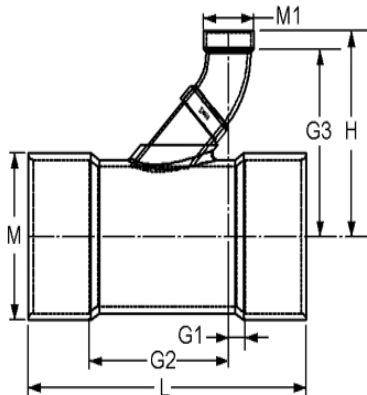

G1 = 1-9/16

G2 = 8-15/16

G3 = 7-5/8

H = 9-1/8

L = 17

M = 7-1/2

M1 = 2-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

