

**Part No:** 3977-582C

**Fabricated CPVC Schedule 80 Combo Wye & 1/8 Bend DWV**

**Desc:** 8X4CPVC RD CMB WYE&1/8 BEND SCH80

**MSRP:** 1474.58

**Part Code:** 099

**Weight(lbs):** 22.809

**Weight(kg):** 10.346

**Weight(gm):** 10346


**Size:** 8 X 4

**Color:** GRAY

**Material:** CPVC

**Type** Reducer

**Connection** Socket x Socket x Socket

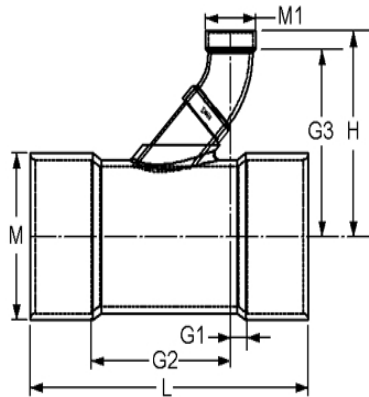

**H** = 13-9/16

**L** = 23

**M** = 9-5/8

**M1** = 5-1/4

**G1** = 1-5/16

**G2** = 13-3/16

**G3** = 11-1/4

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

