

Part No: 3977-626

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 10X6 PVC COMB Y&1/8 BND SOC SCH80

MSRP: 884.02

Part Code: 400

Weight(lbs): 39.258

Weight(kg): 17.807

Weight(gm): 17807


Size: 10 X 6

Color: GRAY

Material: PVC

Schedule SCH 80 DWV-Reducing

Connection Socket x Socket x Socket

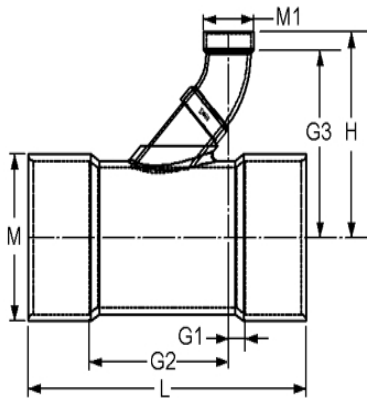

G1 = 1-3/4

G2 = 16-1/2

G3 = 14-1/2

H = 17-9/16

L = 28-3/4

M = 11-15/16

M1 = 7-5/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

