

Part No: 3977-664C

Fabricated CPVC Schedule 80 Combo Wye & 1/8 Bend DWV

Desc: 12X4 CPVC RD COMB WYE&1/8 BEND SOC SCH80

MSRP: 3372.73

Part Code: 099

Weight(lbs): 48.599

Weight(kg): 22.044

Weight(gm): 22044


Size: 12 X 4

Color: GRAY

Material: CPVC

Type Reducer

Connection Socket x Socket x Socket

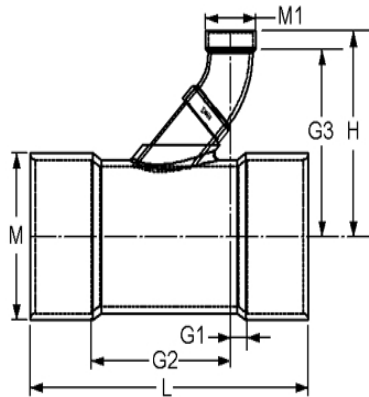

G1 = 1-1/4

G2 = 12-3/4

G3 = 13-1/8

H = 15-7/16

L = 26-1/2

M = 14-1/8

M1 = 5-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

