

Part No: 3977-784

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 18X4 PVC RED COMB WYE&1/8 BEND SOC SCH80

MSRP: 2570.79

Part Code: 400

Weight(lbs): 110.214

Weight(kg): 49.992

Weight(gm): 49992


Size: 18 X 4

Color: GRAY

Material: PVC

Schedule SCH 80 DWV-Reducing

Connection Socket x Socket x Socket

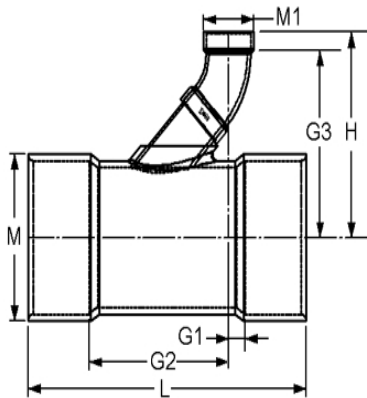

M1 = 5-1/4

G1 = 3-1/2

G2 = 14-1/2

G3 = 15-1/2

H = 17-13/16

L = 36

M = 19-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

