

Part No: 3977-786

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 18X6 PVC RED COMB WYE&1/8 BEND SOC SCH80

MSRP: 2727.13

Part Code: 400

Weight(lbs): 119.268

Weight(kg): 54.099

Weight(gm): 54099


Size: 18 X 6

Color: GRAY

Material: PVC

Schedule SCH 80 DWV-Reducing

Connection Socket x Socket x Socket

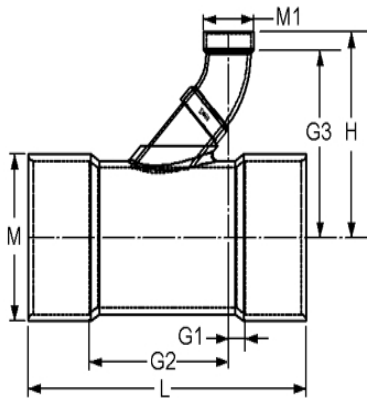

M1 = 7-5/8

G1 = 2-3/8

G2 = 16-1/2

G3 = 17-7/8

H = 20-15/16

L = 36-15/16

M = 19-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

