

Part No: 3977-792

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 18X12 PVC RED COMB WYE&1/8 BND SOC SCH80

MSRP: 4264.9

Part Code: 400

Weight(lbs): 187.415

Weight(kg): 85.01

Weight(gm): 85010


Size: 18 X 12

Color: GRAY

Material: PVC

Schedule SCH 80 DWV-Reducing

Connection Socket x Socket x Socket

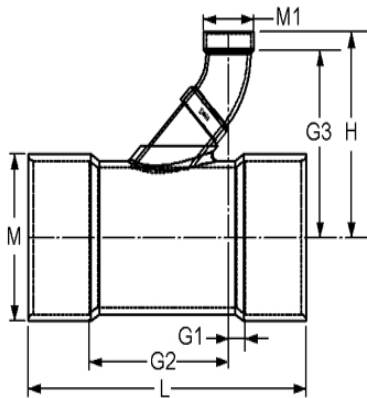

G1 = 1-7/16

G2 = 28-9/16

G3 = 25-5/8

H = 31-3/4

L = 48

M = 19-7/8

M1 = 14-1/4

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

