

Part No: 3977-814

Fabricated DWV

Combo Wye & 1/8 Bend

Desc: 20X4 PVC RED COMB WYE&1/8 BEND SOC SCH80

MSRP: 2844.26

Part Code: 400

Weight(lbs): 144.262

Weight(kg): 65.436

Weight(gm): 65436


Size: 20 X 4

Color: GRAY

Material: PVC

Schedule SCH 80 DWV-Reducing

Connection Socket x Socket x Socket

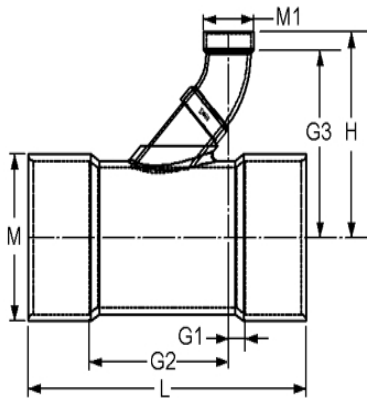

G3 = 16-7/16

H = 18-11/16

L = 38

M = 22-1/16

M1 = 5-1/4

G1 = 3-5/8

G2 = 14-3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

