

Part No: 3978-060

Fabricated DWV

Cleanout Adapter W/Plug

Desc: 6 PVC C/O ADAPTER SPGXTHRD W/PLUG

MSRP: 279.54

Part Code: 400

Weight(lbs): 2.403


Weight(kg): 1.09

Weight(gm): 1090

Size: 6

Color: GRAY

Material: PVC

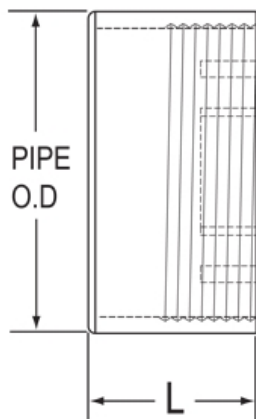

Schedule SCH 80 DWV

Connection Spigot x Cleanout

NOTE Non-Pressure Rated

I = 3-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

