

Part No: 3978-100

Fabricated DWV

Cleanout Adapter W/Plug

Desc: 10 PVC C/O ADAPTER SPGXTHD W/PLUG SCH80

MSRP: 742.6

Part Code: 400

Weight(lbs): 7.782


Weight(kg): 3.53

Weight(gm): 3530

Size: 10

Color: GRAY

Material: PVC

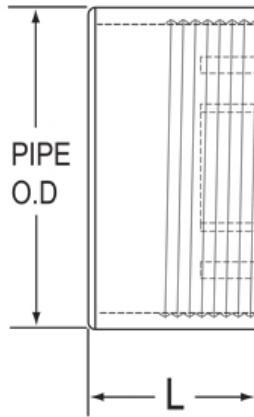

Schedule SCH 80 DWV

Connection Spigot x Cleanout

NOTE Non-Pressure Rated

I = 5-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

