

Part No: 3978-120

Fabricated DWV

Cleanout Adapter W/Plug

Desc: 12 PVC C/O ADAPTER SPGXTHD W/PLUG SCH80

MSRP: 1036.79

Part Code: 400

Weight(lbs): 12.015


Weight(kg): 5.45

Weight(gm): 5450

Size: 12

Color: GRAY

Material: PVC

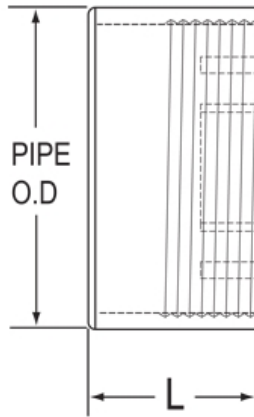

Schedule SCH 80 DWV

Connection Spigot x Cleanout

NOTE Non-Pressure Rated

I = 6-1/2

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

