

Part No: 3990-240

Fabricated DWV

Sanitary Tee

Desc: 24 PVC SANITARY TEE SOC SCH80 G

MSRP: 11280.98

Part Code: 400

Weight(lbs): 684.857

Weight(kg): 310.646

Weight(gm): 310646


Size: 24"

Color: GRAY

Material: PVC

Type Sch 80 DWV

Connection Socket X Socket X Socket

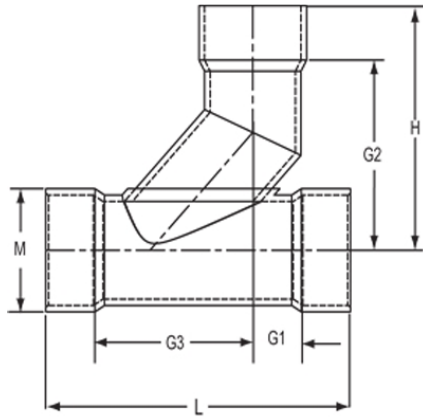

G1 = 12-1/4

G2 = 40-1/4

G3 = 36-9/16

H = 48-9/16

L = 76-1/2

M = 26-7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

