

**Part No:** 401-169

**Schedule 40 White**

**Tee**

**Desc:** 1-1/4X1-1/2 PVC BULLHEAD TEE SOC SCH40

**MSRP:** 9.04

**Part Code:** 040

**Weight(lbs):** 0.302

**Weight(kg):** 0.137

**Weight(gm):** 137


**Size:** 1-1/4"X1-1/4"X1-1/2"

**Color:** WHITE

**Material:** PVC

**Connection** Socket x Socket x Socket

**Type** Reduction

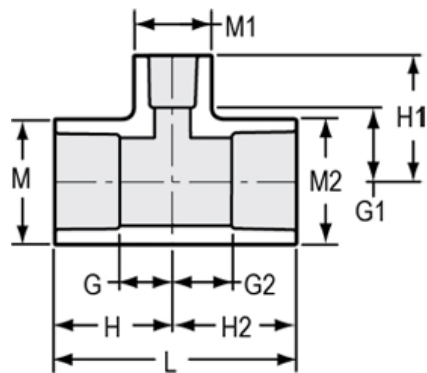

**G** = 1-3/32

**G1** = 1

**G2** = 1-3/32

**H** = 2-11/32

**H1** = 2-5/16

**H2** = 2-11/32

**L** = 4-11/16

**M** = 2

**M1** = 2-1/4

**M2** = 2

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

