

Part No: 401-634F

Fabricated Fittings

Tees

Desc: 10X14 PVC BULLHEAD TEE SOC SCH40

MSRP: 3030.97

Part Code: 047

Weight(lbs): 115.99

Weight(kg): 52.612

Weight(gm): 52612

Size: 10 X 14


Color: WHITE

Material: PVC

Schedule Schedule 40

Connection Socket X Socket X Socket

Type Reduction

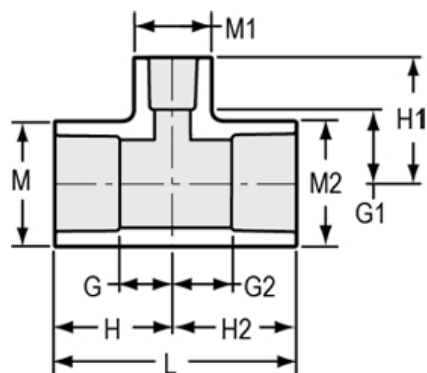

G = 13-11/16

G1 = 11

G2 = 13-11/16

H = 18-11/16

H1 = 18

H2 = 18-11/16

L = 37-7/16

M = 14-7/8

M1 = 14-7/8

M2 = 14-7/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

