

Part No: 401-636F

Fabricated Fittings

Tees

Desc: 10X16 PVC BULLHEAD TEE SOC SCH40

MSRP: 7883.9

Part Code: 047

Weight(lbs): 186.055

Weight(kg): 84.393

Weight(gm): 84393

Size: 10X16


Color: WHITE

Material: PVC

Schedule Schedule 40

Connection Socket X Socket X Socket

Type Reduction

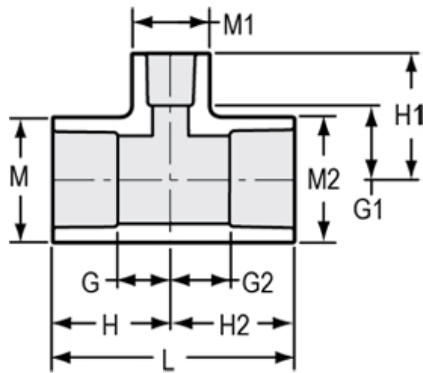

G = 18-5/16

G1 = 12-7/8

G2 = 18-5/16

H = 23-5/16

H1 = 20-7/8

H2 = 23-5/16

L = 46-11/16

M = 17

M1 = 17

M2 = 17

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

