

Part No: 401-914F

Fabricated Fittings

Tees

Desc: 24X14 PVC RED TEE SOC SCH40

MSRP: 6002.07

Part Code: 047

Weight(lbs): 232.742

Weight(kg): 105.57

Weight(gm): 105570

Size: 24"X24"X14"


Color: WHITE

Material: PVC

Schedule Schedule 40

Connection Socket X Socket X Socket

Type Reduction

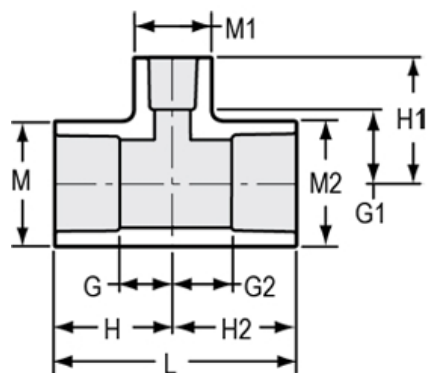

G = 13- 3/4

G1 = 15- 3/4

G2 = 13- 3/4

H = 25- 3/4

H1 = 22- 3/4

H2 = 25- 3/4

L = 51- 1/2

M = 25- 3/8

M1 = 14- 7/8

M2 = 25- 3/8

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ inch. & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

