

**Part No:** 402-003

**Schedule 40 White**

**Tee**

**Desc:** 3/8 PVC TEE SOCXFPT SCH40

**MSRP:** 4.21

**Part Code:** 040

**Weight(lbs):** 0.064

**Weight(kg):** 0.029

**Weight(gm):** 29


**Size:** 3/8"

**Color:** WHITE

**Material:** PVC

**Connection** Socket x Socket x Fipt

**Type** Standard

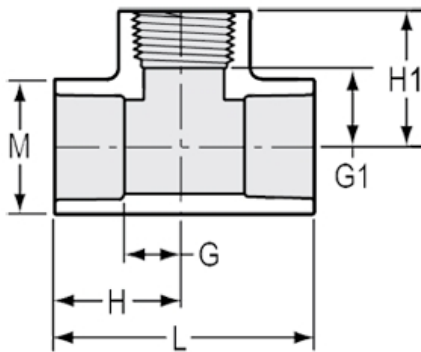

**G** = 7/16

**G1** = 1/2

**H** = 1-11/16

**H1** = 1- 1/16

**L** = 3- 3/8

**M** = 29/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

