

Part No: 402-007G

Schedule 40 Gray

Tee

Desc: 3/4 PVC TEE SOCXFPT SCH40 GRAY

MSRP: 3.04

Part Code: 043

Weight(lbs): 0.115

Weight(kg): 0.052

Weight(gm): 52


Size: 3/4"

Color: GRAY

Material: PVC

Connection Socket x Socket x Fipt

Type Standard

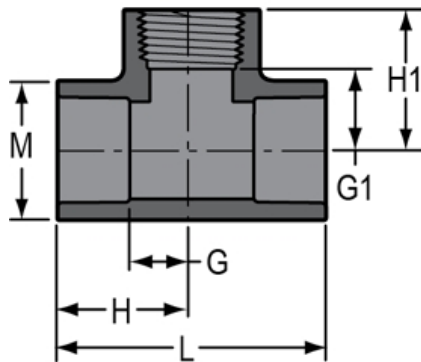

$$G = 21/32$$

$$G1 = 23/32$$

$$H = 1-21/32$$

$$H1 = 1-7/16$$

$$L = 3-9/32$$

$$M = 1-5/16$$

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

