

Part No: 402-012SR

Schedule 40 White

Tee

Desc: 1-1/4 PVC TEE SOCXSRFPT SCH40

MSRP: 26.6

Part Code: 046

Weight(lbs): 0.315

Weight(kg): 0.143

Weight(gm): 143


Size: 1-1/4"

Color: WHITE

Material: PVC

Connection Socket x Socket x SR Fipt

Type Standard

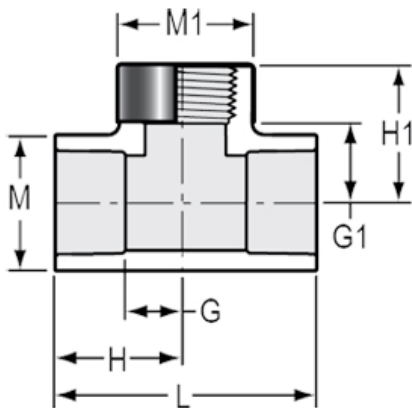

G = 29/32

G1 = 1-1/8

H = 2-5/32

H1 = 2-1/16

M = 2

M1 = 2- 1/16

L = 4-5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

