

Part No: 402-025

Schedule 40 White

Tee

Desc: 2-1/2 PVC TEE SOCXFPT SCH40

MSRP: 40.84

Part Code: 040

Weight(lbs): 0.957

Weight(kg): 0.434

Weight(gm): 434


Size: 2-1/2"

Color: WHITE

Material: PVC

Connection Socket x Socket x Fipt

Type Standard

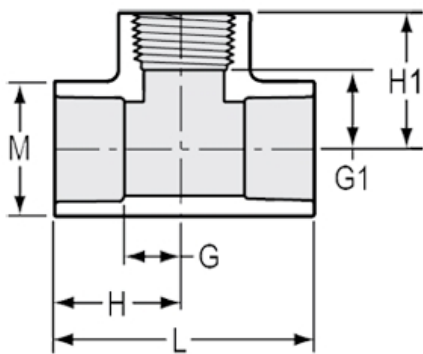

G = 1- 1/2

G1 = 1-19/32

H = 3- 1/4

H1 = 2-29/32

L = 6- 1/2

M = 3-11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

