

Part No: 402-040

Schedule 40 White

Tee

Desc: 4 PVC TEE SOCXFPT SCH40

MSRP: 79.54

Part Code: 040

Weight(lbs): 2.238

Weight(kg): 1.015

Weight(gm): 1015


Size: 4"

Color: WHITE

Material: PVC

Connection Socket x Socket x Fipt

Type Standard

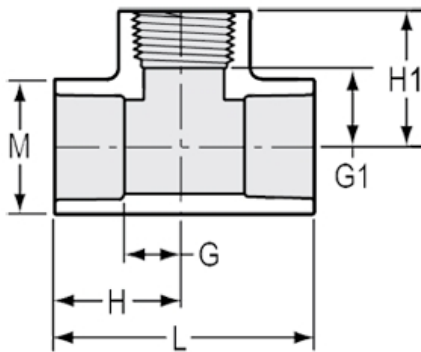

G = 2- 5/16

G1 = 2-13/32

H = 4-11/32

H1 = 3-7/8

L = 8-11/16

M = 5- 1/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

