

**Part No:** 402-490

**Schedule** 40 White

**Tee**

**Desc:** 5X4 PVC RED TEE SOCXFPT SCH40

**MSRP:** 179.93

**Part Code:** 040

**Weight(lbs):** 3.688

**Weight(kg):** 1.673

**Weight(gm):** 1673


**Size:** 5"X5"X4"

**Color:** WHITE

**Material:** PVC

**Connection** Socket x Socket x Fipt

**Type** Reduction

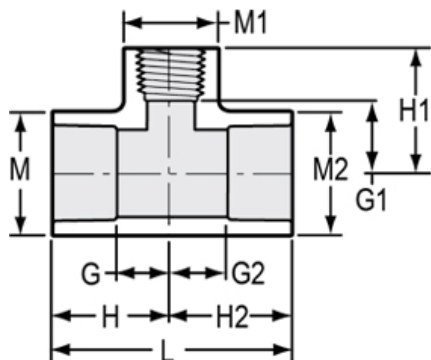

**G** = 2- 1/2

**G1** = 3-11/32

**G2** = 2- 1/2

**M2** = 6-1/8

**L** = 11-1/8

**M** = 6-1/8

**M1** = 5- 1/32

**H** = 5-9/16

**H1** = 5-1/16

**H2** = 5-9/16

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

**L** = Overall length of fittings; ± 1/16 inch.

**M** = Outside diameter of socket/thread hub; ± 1/16 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/16 inch.

**W** = Height of cap; ± 1/16 inch

## Typical Molded Dimension References

