

**Part No:** 402-623F

**Fabricated Fittings**

**Tees**

**Desc:** 10X3 PVC RED TEE SOCXFPT SCH40 FAB

**MSRP:** 1051.19

**Part Code:** 047

**Weight(lbs):** 20.812

**Weight(kg):** 9.44

**Weight(gm):** 9440

**Size:** 10"X10"X3"


**Color:** WHITE

**Material:** PVC

**Schedule** Schedule 40

**Connection** Socket X Socket X FIPT

**Type** Reduction

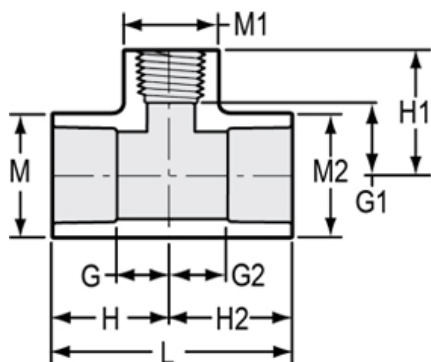

**G** = 5-3/8

**G1** = 6-3/8

**G2** = 5-3/8

**H** = 10-5/8

**H1** = 8

**H2** = 10-5/8

**L** = 21-1/4

**M** = 11-1/2

**M1** = 4

**M2** = 11-1/2

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

**L** = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

**M** = Outside diameter of socket/thread hub; ± 1/4 inch.

**N** = Socket bottom to socket bottom; couplings; ± 1/2 inch.

**W** = Height of cap; ± 1/4 inch.

## Typical Fabricated Dimension References

