

Part No: 406-003

Schedule 40 White

Elbow

Desc: 3/8 PVC 90 ELL SOC SCH40

MSRP: 5.43

Part Code: 040

Weight(lbs): 0.029

Weight(kg): 0.013

Weight(gm): 13

Size: 3/8"


Color: WHITE

Material: PVC

Connection Socket x Socket

Angle 90°

Type Standard

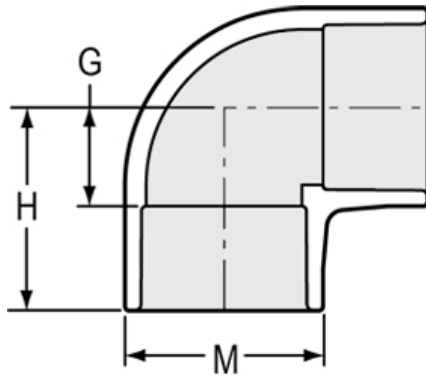

G = 3/8

H = 1- 1/8

M = 7/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

