

Part No: 406-020S

Schedule 40 White

Elbow

Desc: 2 PVC SWEEP ELL SOC SCH40

MSRP: 26.59

Part Code: 040

Weight(lbs): 0.52

Weight(kg): 0.236

Weight(gm): 236

Size: 2"


Color: WHITE

Material: PVC

Connection Sweep - Short

Angle 90°

Type Standard

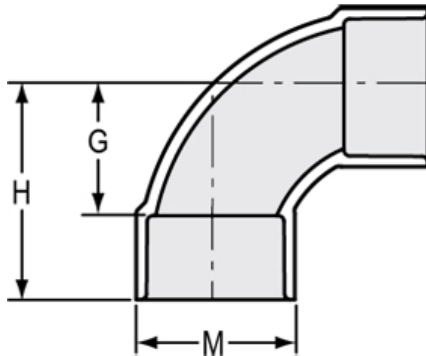

G = 2-5/16

H = 3-11/16

M = 2-13/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

