

**Part No:** 406-025G

**Schedule 40 Gray**

**Elbow**

**Desc:** 2-1/2 PVC 90 ELL SOC SCH40 GRAY

**MSRP:** 21.82

**Part Code:** 043

**Weight(lbs):** 0.719

**Weight(kg):** 0.326

**Weight(gm):** 326

**Size:** 2-1/2"


**Color:** GRAY

**Material:** PVC

**Connection** Socket x Socket

**Angle** 90°

**Type** Standard

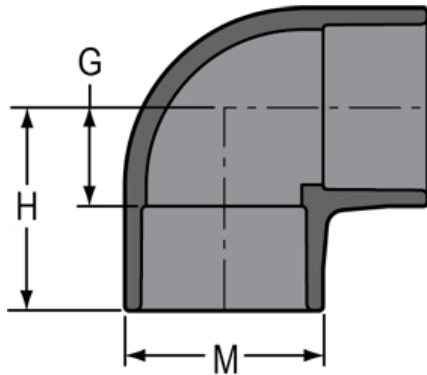

**G** = 1-17/32

**H** = 3-5/16

**M** = 3-11/32

## Injection Molded Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/32$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows tees, crosses;  $\pm 1/32$  inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/32$  inch

**L** = Overall length of fittings;  $\pm 1/16$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/16$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/16$  inch.

**W** = Height of cap;  $\pm 1/16$  inch

## Typical Molded Dimension References

