

Part No: 406-045F

Fabricated Fittings

Elbow

Desc: 4-1/2 PVC 90 ELL SOC SCH40

MSRP: 299.86

Part Code: 047

Weight(lbs): 3.549


Weight(kg): 1.61

Weight(gm): 1610

Size: 4-1/2"

Color: WHITE

Material: PVC

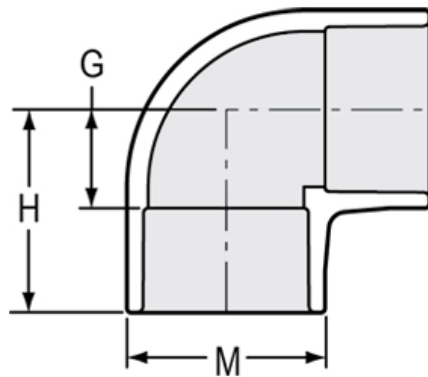

Schedule SCH 40

Angle 90 Degree

Connection Socket X Socket

Type Standard

G = 8- 5/8

H = 6- 1/8

M = 5- 7/16

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/4 & larger ± 1/2 inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; ± 1/4 inch.; wyes ± 1/2 inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/4 inch; 14" & larger ± 1/2 inch.

L = Overall length of fittings; ± 1/2 inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; ± 1/4 inch.

N = Socket bottom to socket bottom; couplings; ± 1/2 inch.

W = Height of cap; ± 1/4 inch.

Typical Fabricated Dimension References

