

Part No: 406-080LSF

Fabricated Fittings

Elbow

Desc: 8 PVC LONG SWEEP 90 ELL SOC SCH40

MSRP: 505.03

Part Code: 047

Weight(lbs): 18.958

Weight(kg): 8.599

Weight(gm): 8599

Size: 8"

Color: WHITE


Material: PVC

Schedule SCH 40

Angle 90 Degree

Connection Long Sweep

Type Standard

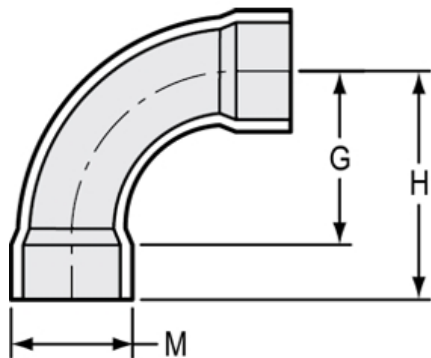

$$G = 22 - 7/16$$

$$H = 26 - 11/16$$

$$M = 9 - 1/4$$

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

