

Part No: 406-100G

Schedule 40 Gray

Elbow

Desc: 10 PVC 90 ELL SOC SCH40 GRAY

MSRP: 1444.16

Part Code: 043

Weight(lbs): 15.653

Weight(kg): 7.1

Weight(gm): 7100

Size: 10"


Color: GRAY

Material: PVC

Connection Socket x Socket

Angle 90°

Type Standard

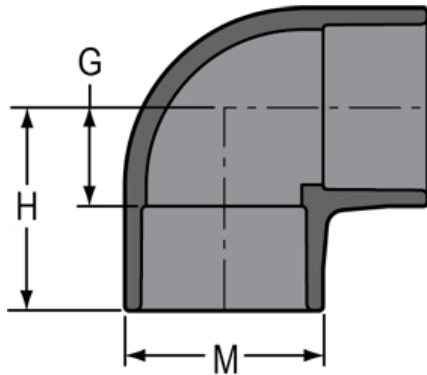

G = 5-27/32

H = 10-27/32

M = 11-19/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

