

Part No: 406-120G

Schedule 40 Gray

Elbow

Desc: 12 PVC 90 ELL SOC SCH40

MSRP: 1936.97

Part Code: 043

Weight(lbs): 25.964

Weight(kg): 11.777

Weight(gm): 11777

Size: 12"


Color: GRAY

Material: PVC

Connection Socket x Socket

Angle 90°

Type Standard

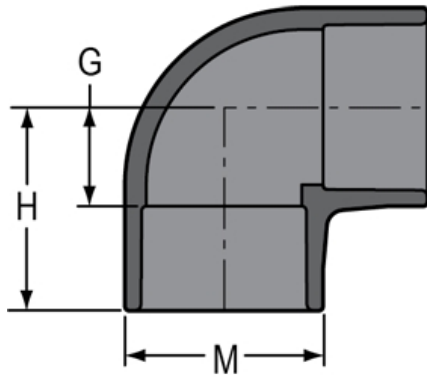

G = 6-15/16

H = 12-15/16

M = 13-11/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

