

Part No: 407-101G

Schedule 40 Gray

Elbow

Desc: 3/4X1/2 PVC RED 90 SOCXFPT SCH40 GRAY

MSRP: 1.8

Part Code: 043

Weight(lbs): 0.073


Weight(kg): 0.033

Weight(gm): 33

Size: 3/4"X1/2"

Color: GRAY

Material: PVC

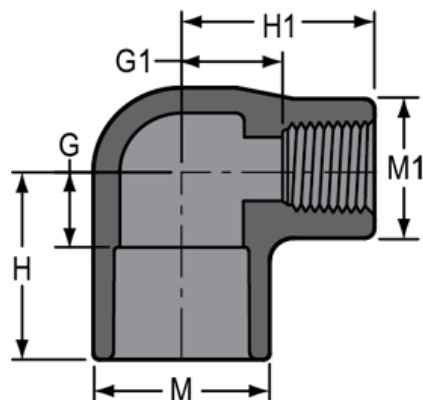

Connection Socket x Fipt

Angle 90°

Type Reduction

G = 9/16

G1 = 5/8

H = 1- 1/2

H1 = 1- 3/8

M = 1- 5/16

M1 = 1- 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

