

Part No: 410-005B

Schedule 40 Black

Elbow

Desc: 1/2 PVC 90 ST ELL MPTXSOC SCH40 BLACK

MSRP: 2.48

Part Code: 011

Weight(lbs): 0.042

Weight(kg): 0.019

Weight(gm): 19


Size: 1/2"

Color: BLACK

Material: PVC Black

Connection Mipt x Socket

Type 90° Street Elbow

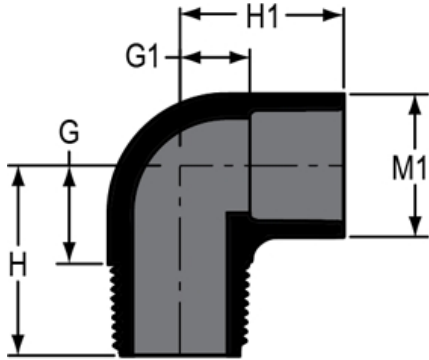

G = 11/16

G1 = 13/32

M1 = 1-3/32

H = 1-3/8

H1 = 1-5/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch


L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

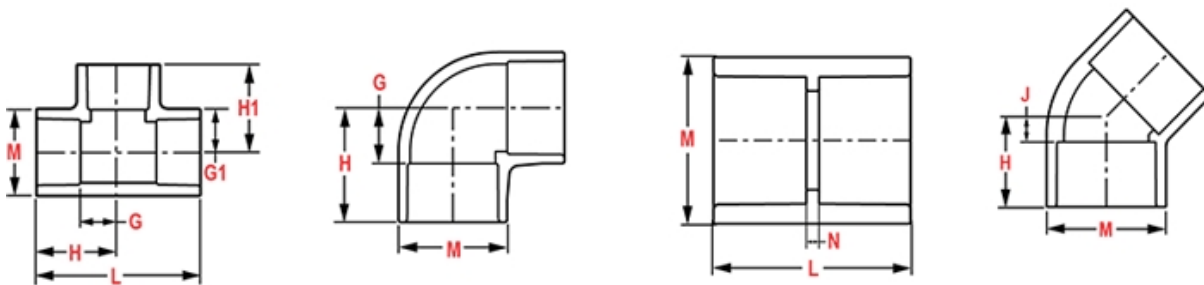

The information printed here is based on current information & product design at the time of publication and is subject to change without notification. Spears® ongoing commitment to product improvement may result in some variation. No representation, guarantees or warranties of any kind are as to its accuracy, suitability for particular application or results to be obtained therefrom. For verification of technical data or additional information, please contact Spears® Technical Service Department :: WEST COAST : (818) 364-1611 - EAST COAST : (717) 938-9006