

Part No: 410-007G

Schedule 40 Gray

Elbow

Desc: 3/4 PVC 90 ST ELL MPTXSOC SCH40 GRAY

MSRP: 3.04

Part Code: 043

Weight(lbs): 0.075

Weight(kg): 0.034

Weight(gm): 34

Size: 3/4"


Color: GRAY

Material: PVC

Connection Mipt x Socket

Angle 90°

Type Standard

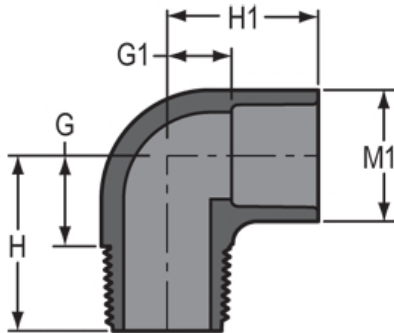

G = 27/32

G1 = 15/32

H = 1-17/32

H1 = 1-15/32

M1 = 1- 5/16

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

