

Part No: 411-015

Schedule 40 White

Elbow

Desc: 1-1/2 PVC 11-1/4 ELL SOC SCH40

MSRP: 9.34

Part Code: 040

Weight(lbs): 0.243

Weight(kg): 0.11

Weight(gm): 110

Size: 1-1/2"


Color: WHITE

Material: PVC

Connection Socket x Socket

Angle 11-1/4°

Type Standard

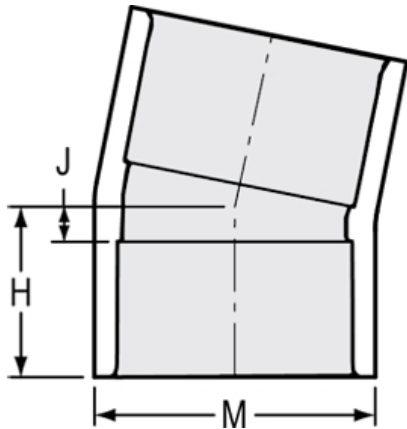

H = 1-19/32

J = 7/32

M = 2-3/8

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

