

**Part No:** 411-015F

**Fabricated Fittings**

**Elbow**

**Desc:** 1-1/2 PVC 11-1/4 ELL SOC SCH40 FAB

**MSRP:** 43.86

**Part Code:** 047

**Weight(lbs):** 0.223


**Weight(kg):** 0.101

**Weight(gm):** 101

**Size:** 1-1/2"

**Color:** WHITE

**Material:** PVC

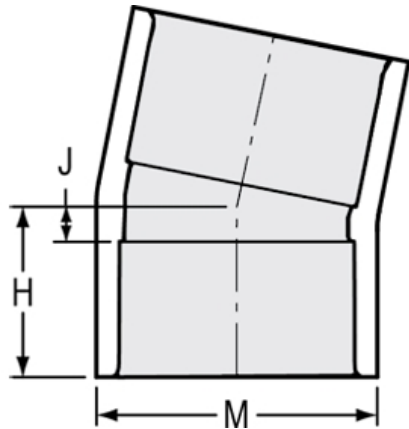

**H** = 2

**J** = 1/2

**M** = 2- 3/16

**Schedule** SCH 40

**Angle** 11-1/4 Degree

**Connection** Socket X Socket

**Type** Standard

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

