

Part No: 411-020

Schedule 40 White

Elbow

Desc: 2 PVC 11-1/4 ELL SOC SCH40

MSRP: 10.86

Part Code: 040

Weight(lbs): 0.331

Weight(kg): 0.15

Weight(gm): 150

Size: 2"


Color: WHITE

Material: PVC

Connection Socket x Socket

Angle 11-1/4°

Type Standard

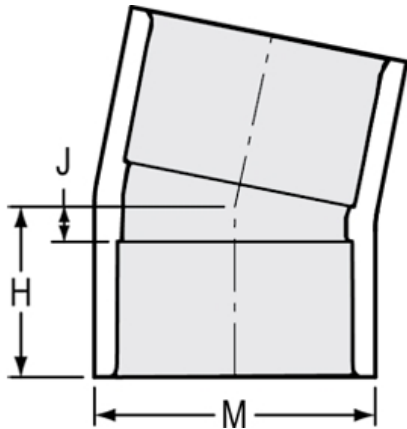

H = 1-23/32

J = 7/32

M = 2-27/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

