

**Part No:** 411-180F

**Fabricated Fittings**

**Elbow**

**Desc:** 18 PVC 11-1/4 ELL SOC SCH40 FAB

**MSRP:** 1152.48

**Part Code:** 047

**Weight(lbs):** 42.924


**Weight(kg):** 19.47

**Weight(gm):** 19470

**Size:** 18"

**Color:** WHITE

**Material:** PVC

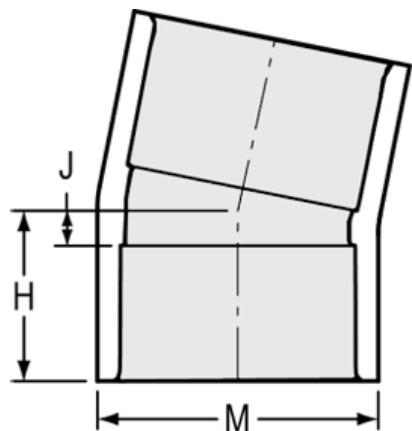

**H** = 11-11/16

**J** = 2-11/16

**M** = 19- 1/8

**Schedule** SCH 40

**Angle** 11-1/4 Degree

**Connection** Socket X Socket

**Type** Standard

## Fabricated Dimension References:

**G** = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses;  $\pm 1/4$  & larger  $\pm 1/2$  inch.

**H** = Intersection of center lines to face of fitting; 90° elbows, tees, crosses;  $\pm 1/4$  inch.; wyes  $\pm 1/2$  inch; 14" & larger inch.

**J** = Intersection of center lines to bottom of socket/thread; 45° elbows;  $\pm 1/4$  inch; 14" & larger  $\pm 1/2$  inch.

**L** = Overall length of fittings;  $\pm 1/2$  inch; wyes  $\pm 1$  inch; 14" & larger  $\pm 1$  inch.

**M** = Outside diameter of socket/thread hub;  $\pm 1/4$  inch.

**N** = Socket bottom to socket bottom; couplings;  $\pm 1/2$  inch.

**W** = Height of cap;  $\pm 1/4$  inch.

## Typical Fabricated Dimension References

