

Part No: 412-005G

Schedule 40 Gray

Elbow

Desc: 1/2 PVC 90 ST ELL MPTXFPT SCH40 GRAY

MSRP: 3.56

Part Code: 043

Weight(lbs): 0.049


Weight(kg): 0.022

Weight(gm): 22

Size: 1/2"

Color: GRAY

Material: PVC

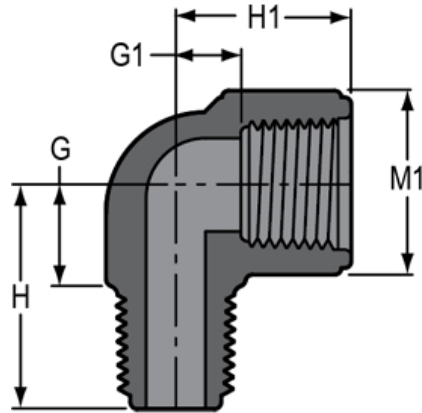

Connection Mipt x Fipt

Angle 90°

Type Standard

G1 = 11/32

H = 1-13/32

H1 = 1-1/16

M1 = 1-1/8

G = 23/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

