

Part No: 412-007G

Schedule 40 Gray

Elbow

Desc: 3/4 PVC 90 ST ELL MPTXFPT SCH40 GRAY

MSRP: 4.34

Part Code: 043

Weight(lbs): 0.068


Weight(kg): 0.031

Weight(gm): 31

Size: 3/4"

Color: GRAY

Material: PVC

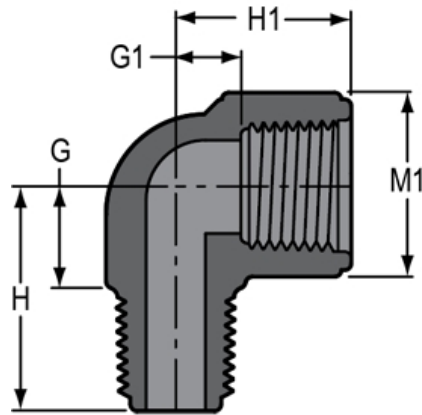

Connection Mipt x Fipt

Angle 90°

Type Standard

G = 7/8

G1 = 15/32

H = 1-9/16

H1 = 1-3/16

M1 = 1-11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

