

Part No: 412-030

Schedule 40 White

Elbow

Desc: 3 PVC 90 ELL MPTXFPT SCH40

MSRP: 60.97

Part Code: 040

Weight(lbs): 1.354


Weight(kg): 0.614

Weight(gm): 614

Size: 3"

Color: WHITE

Material: PVC

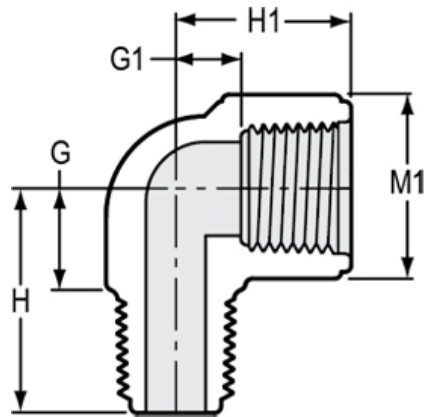

Connection Mipt x Fipt

Angle 90°

Type Standard

G = 2-3/4

G1 = 1-29/32

H = 4-1/16

H1 = 3-5/16

M1 = 4

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

