

Part No: 4135-010SS

EverTUFF® CTS

Adapter

Desc: 1" CPVC SS TRNS FEM ADPT

MSRP: 35.9

Part Code: 036

Weight(lbs): 0.284

Weight(kg): 0.129

Weight(gm): 129

Size: 1


Color: TAN

Material: CPVC

Type Transition Female Adapter

Connection Socket x SS Fipt

Note LEAD FREE

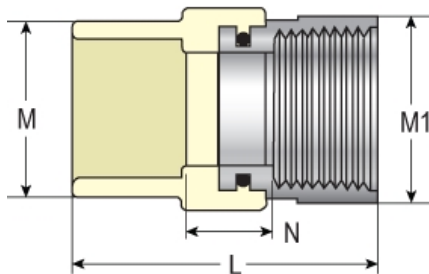

M = 1-3/8

M1 = 1-21/32

N = 5/8

L = 2-11/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

