

Part No: 414-005

Schedule 40 White

Elbow

Desc: 1/2 PVC S/O 90 ELL SOCXFPT SCH40

MSRP: 5.71

Part Code: 040

Weight(lbs): 0.071


Weight(kg): 0.032

Weight(gm): 32

Size: 1/2"

Color: WHITE

Material: PVC

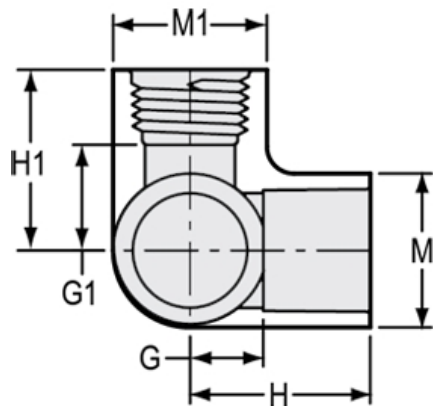

Connection Soc x Soc x Fipt (Side Outlet)

Angle 90°

Type Standard

G = 1/2

G1 = 17/32

H = 1- 1/4

H1 = 1- 1/4

M = 1- 3/32

M1 = 1- 3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

