

Part No: 414-130

Schedule 40 White

Elbow

Desc: 1X1/2 PVC SIDE OUT 90 ELL SOCXFPT SCH40

MSRP: 9.68

Part Code: 040

Weight(lbs): 0.146


Weight(kg): 0.066

Weight(gm): 66

Size: 1"X1"X1/2"

Color: WHITE

Material: PVC

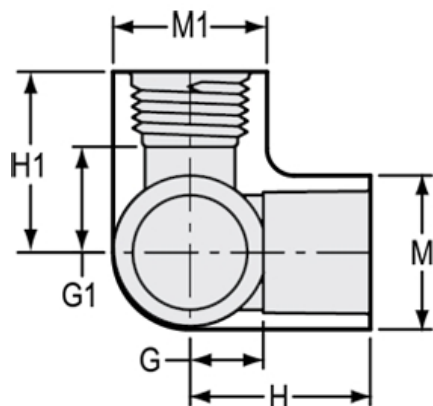

Connection Soc x Soc x Fipt (Side Outlet)

Angle 90°

Type Reduction

G = 11/16

G1 = 13/16

H = 1-13/16

H1 = 1-9/16

M = 1-5/8

M1 = 1-3/32

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/32$ inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; $\pm 1/32$ inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/32$ inch

L = Overall length of fittings; $\pm 1/16$ inch.

M = Outside diameter of socket/thread hub; $\pm 1/16$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/16$ inch.

W = Height of cap; $\pm 1/16$ inch

Typical Molded Dimension References

