

Part No: 4141-007

EverTUFF® CTS

Coupling

Desc: 3/4 CPVC CTS TRANSITION COUP IPSXCTS SOC

MSRP: 4.76

Part Code: 035

Weight(lbs): 0.042


Weight(kg): 0.019

Weight(gm): 19

Size: 3/4"

Color: TAN

Material: CPVC

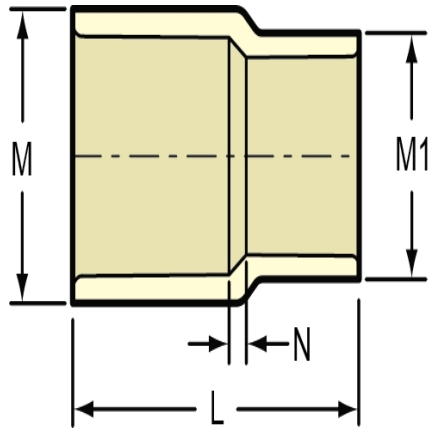

L = 1-27/32

M = 1-5/16

M1 = 1-3/32

N = 1/8

Type Transition Coupling

Connection IPS Socket x CTS Socket

NSF® Certified LEAD FREE

Injection Molded Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; ± 1/32 inch.

H = Intersection of center lines to face of fitting; 90° elbows tees, crosses; ± 1/32 inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; ± 1/32 inch

L = Overall length of fittings; ± 1/16 inch.

M = Outside diameter of socket/thread hub; ± 1/16 inch.

N = Socket bottom to socket bottom; couplings; ± 1/16 inch.

W = Height of cap; ± 1/16 inch

Typical Molded Dimension References

