

Part No: 415-045F

Fabricated Fittings

Elbow

Desc: 4-1/2 PVC 30 ELL SOC SCH40 FAB

MSRP: 109.24

Part Code: 047

Weight(lbs): 1.482


Weight(kg): 0.672

Weight(gm): 672

Size: 4-1/2"

Color: WHITE

Material: PVC

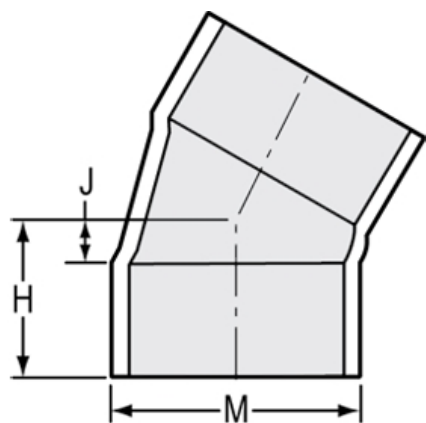

H = 3-3/4

J = 1-1/4

M = 5-7/16

Schedule SCH 40

Angle 30 Degree

Connection Socket X Socket

Type Standard

Fabricated Dimension References:

G = (LAYING LENGTH) intersection of center lines to bottom of socket/thread; 90° elbows, tees, crosses; $\pm 1/4$ & larger $\pm 1/2$ inch.

H = Intersection of center lines to face of fitting; 90° elbows, tees, crosses; $\pm 1/4$ inch.; wyes $\pm 1/2$ inch; 14" & larger inch.

J = Intersection of center lines to bottom of socket/thread; 45° elbows; $\pm 1/4$ inch; 14" & larger $\pm 1/2$ inch.

L = Overall length of fittings; $\pm 1/2$ inch; wyes ± 1 inch; 14" & larger ± 1 inch.

M = Outside diameter of socket/thread hub; $\pm 1/4$ inch.

N = Socket bottom to socket bottom; couplings; $\pm 1/2$ inch.

W = Height of cap; $\pm 1/4$ inch.

Typical Fabricated Dimension References

